



Model Number


V93-W-YE2M-STOOW

Female cordset, 7/8", 3-pin, STOOW cable

Features

- Thread 7/8"

Dimensions

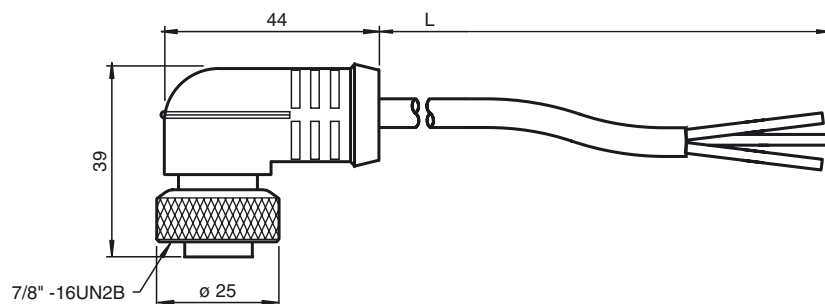

Technical data

General specifications

Number of pins	3
Connection 1	socket
Construction type 1	right angle
Threading 1	7/8"
Connection 2	cable end

Electrical specifications

Operating voltage	U_B	max. 600 V
Test voltage		1500 V
Operating current		13 A
Volume resistance		< 5 m Ω

Ambient conditions

Ambient temperature	-40 ... 105 °C (-40 ... 221 °F)
---------------------	---------------------------------


Mechanical specifications

Protection degree	IP67
Material	
Contacts	Cu alloy gold plated
Body	PVC, yellow
Cable	PVC
Slotted nut	clear anodized aluminum
Core insulation	PVC
Cable	fine-strand, flexible
Sheath diameter	Ø 9.9 mm
Bending radius	10 x cable diameter
Color	yellow
Cores	3 x 1.5 mm ² (16 AWG)
Length	L
Note	STOOW UL Standard

Approvals and certificates

UL approval	cULus Listed, General Purpose
-------------	-------------------------------

Electrical connection

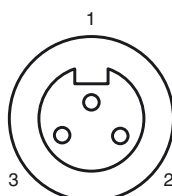

1	GN/YE
2	BK
3	WH